

85 01 250 US

KNIPEX SmartGrip® Water Pump Pliers with automatic adjustment



PATENTED



- ideal for frequent changeovers to workpieces of different sizes
- automatic adjustment per one-hand operation both for right-handed and left-handed use
- good access to the workpiece thanks to the slim dimensions in the head and joint area and flush joint bolt
- self-locking on pipes and nuts: no slipping on the workpiece and low handforce required
- gripping surfaces with special hardened teeth, teeth hardness approx. 61 HRC: low wear and stable gripping
- box-joint design: high stability because of double guide
- guard prevents operators' fingers being pinched
- locking lever for space saving transport with reliable closed handles
- Chrome vanadium electric steel, forged, oil-hardened

Adjustment to suit the workpiece is automatic with the KNIPEX SmartGrip®! Place the outer jaw on the workpiece, squeeze the handles - turn!

Article No.	85 01 250 US
EAN	843221003159
Pliers	grey atramentized
Head	polished
Handles	with non-slip plastic coating
Capacities for pipes Ø Inch	1 1/4
Capacities for pipes Ø mm	32
Capacities for nuts mm	36
Length mm	250
Net weight g	370




Automatic adjustment: no time-consuming trial and error-adjusting to find the correct opening size in case of differently sized workpieces (e.g. the red highlighted nuts and fittings). Everything done with a single grasp.



Locking lever for space saving transport with reliable closed handles



Slim dimensions for good access to the workpiece using one-hand operation

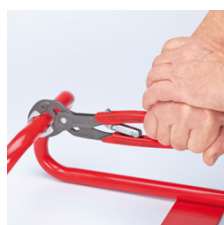

Self-locking on pipes and nuts: no slipping on the workpiece

technical change and errors excepted