


Louvered Panel & Bin Combination Guide


for AkroBins® & Louvered Panels manufactured by **AKRO-MILS®**

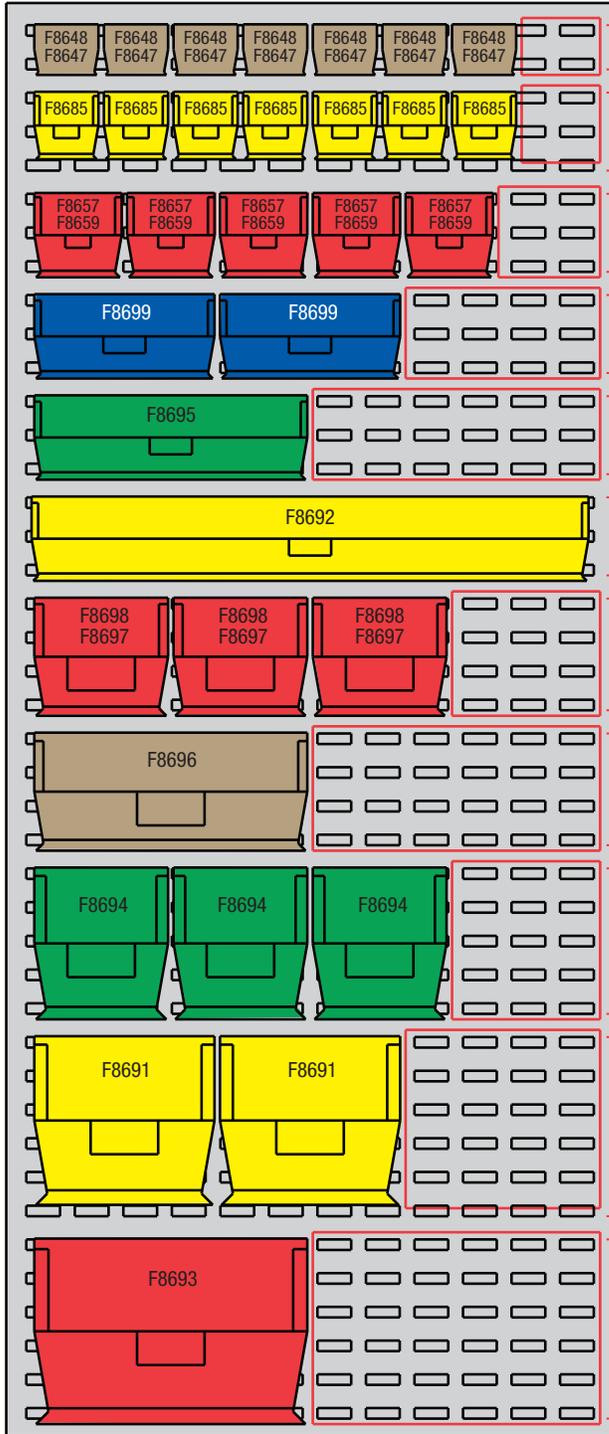

- F8648, F8647**
Each bin is 1-1/2 louvers wide.
Each row of bins uses two rows of louvers.
- F8685**
Each bin is 1-1/2 louvers wide.
Each row of bins uses three rows of louvers.
- F8657, F8659**
Each bin is 2 louvers wide.
Each row of bins uses three rows of louvers.
- F8699**
Each bin is 4 louvers wide.
Each row of bins uses three rows of louvers.
- F8695**
Each bin is 6 louvers wide.
Each row of bins uses three rows of louvers.
- F8692**
Each bin is 12 louvers wide.
Each row of bins uses three rows of louvers.
- F8698, F8697**
Each bin is 3 louvers wide.
Each row of bins uses four rows of louvers.
- F8696**
Each bin is 6 louvers wide.
Each row of bins uses four rows of louvers.
- F8694**
Each bin is 3 louvers wide.
Each row of bins uses five rows of louvers.
- F8691**
Each bin is 4 louvers wide.
Each row of bins uses six rows of louvers.
- F8693**
Each bin is 6 louvers wide.
Each row of bins uses six rows of louvers.



| Number Of Louvers Per Panel | | |
|-----------------------------|---------------|-------------|
| Product Number | Number Across | Number Down |
| H4608 | 6 | 9 |
| H4609 | 12 | 9 |
| 40L708 | 17 | 16 |
| H4610 | 9 | 10 |
| 1UMD9 | 12 | 10 |
| H3996 | 12 | 30 |
| 1UMD7 | 6 | 30 |
| 4TJ79 | 12 per side | 36 per side |
| H3972 | 12 | 30 |
| 1UME1 | 6 | 30 |
| H4579 | 12 per side | 30 per side |
| 1UME5 | 12 | 36 |
| 30650 | 17 | 16 |
| 30656 | 17 | 16 |
| 30658 | 6 | 30 per side |
| 30606 | 17 per side | 16 per side |
| 30607 | 17 per side | 16 per side |
| 30637 | 12 | 5 |
| 40K012 | 12 | 5 |
| 40K014 | 12 | 30 |
| 30654 | 12 per side | 30 per side |
| 30536 | 12 | 12 |
| 30553 | 7 | 23 |
| 98536 | 12 per side | 12 per side |

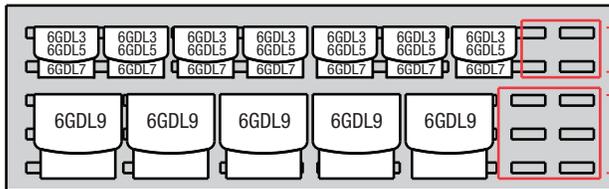

- 6GDL3, 6GDL5, 6GDL7**
Each bin is 1-1/2 louvers wide.
Each row of bins uses two rows of louvers.
- 6GDL9**
Each bin is 2 louvers wide.
Each row of bins uses three rows of louvers.