

# LIBMAN<sup>®</sup>

## COMMERCIAL



QUALITY CLEANING PRODUCTS FOR COMMERCIAL USE!

1.25 MILLION SQ. FEET  
MANUFACTURING FACILITY

The Libman Company is a 4<sup>th</sup> generation family owned company, proudly making our products in the USA since 1896. Over the past 15 years, Libman Commercial has evolved to focus on the special needs of each market segment, from industrial to housekeeping, to food service.

### Top Selling Products

#### MULTI-SURFACE PUSH BROOM

TOP  
SELLER



GIS# 6APWO | 24" Multi-Surface Push Broom

#### LOBBY PAN SET

TOP  
SELLER



GIS# 9DZE2 | Open Lid Lobby Dust Pan & Broom

- Specialized, unique and high quality offering
- Deepest offering in the broom, brush, and mop industry
- 90-95% of the Libman line is manufactured from component to finished product in our plant
- Extensive finished goods and component inventory; all orders can be filled and shipped in 2-4 days
- Highest service rates in the industry, often exceeding 98-99%

# Complete Push Broom Sets

## THREADED

TOP  
SELLER

### Smooth Surface

- Polymer broom block for durability and hygiene.
- 1" x 60" long steel, nylon thread handle with 5" handgrip, hanger hole.
- 3" long, soft, recycled PET, staple-set fibers.
- Resin bolt locks handle in place.
- Excellent for smooth concrete floors in garages and factories.



GIS# 6APWI | 24" Smooth Surface Push Broom  
GIS# 46U284 | 18" Smooth Surface Push Broom  
GIS# 8ZD24 | 60" Steel Replacement Handle

TOP  
SELLER

### Multi-Surface


- Polymer broom block for durability and hygiene.
- 1" x 60" long steel, nylon thread handle with 5" handgrip, hanger hole.
- 3" long, combo of firm and flexible split tip recycled PET, staple-set fibers.
- Resin bolt locks handle in place.
- Excellent for all surface types.



GIS# 6APW0 | 24" Multi-Surface Push Broom  
GIS# 46U282 | 18" Multi-Surface Push Broom  
GIS# 8ZD24 | 60" Steel Replacement Handle

### Rough Surface

- Polymer broom block for durability and hygiene.
- 1" x 60" long steel, nylon thread handle with 5" handgrip, hanger hole.
- 4" long, stiff, recycled PET, staple-set fibers.
- Resin bolt locks handle in place.
- Excellent for outdoor applications or any non-smooth surfaces.

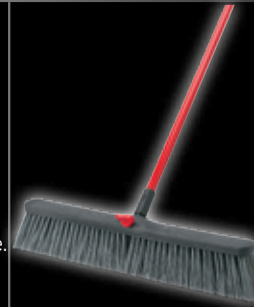

GIS# 9MLA2 | 24" Rough Surface Push Broom  
GIS# 46U283 | 18" Rough Surface Push Broom  
GIS# 8ZD24 | 60" Steel Replacement Handle

## HEAVY DUTY

TOP  
SELLER

### Smooth Surface

- 36" natural hardwood broom block.
- 1" x 60" long steel, nylon thread handle with 5" handgrip and hanger hole.
- 3" long, soft, recycled PET, staple-set fibers.
- Super tough polymer brace won't rust or bend.
- Flagged fibers pick up fine dirt & dust.
- Excellent for large spaces, such as warehouse and factory floors.



GIS# 8G793 | 36" Smooth Surface Heavy Duty Push Broom  
GIS# 8ZD24 | 60" Steel Replacement Handle

### Multi-Surface

- Polymer broom block for durability and hygiene.
- 1" x 60" long steel, nylon thread handle with 5" handgrip and hanger hole.
- 3" long, combo of firm and flexible split tip recycled PET, staple-set fibers.
- Super tough polymer brace won't rust or bend.
- Excellent for all surface types.



GIS# 46U285 | 24" Multi-Surface Push Broom  
GIS# 8TN94 | 18" Multi-Surface Push Broom  
GIS# 8ZD24 | 60" Steel Replacement Handle

### Rough Surface

- Polymer broom block for durability and hygiene.
- 1" x 60" long steel, nylon thread handle with 5" handgrip and hanger hole.
- 4" long, stiff, recycled PET, staple-set fibers.
- Super tough polymer brace won't rust or bend.
- Excellent for outdoor applications or any non-smooth surfaces.



GIS# 46U286 | 24" Rough Surface Push Broom  
GIS# 8ZD25 | 18" Rough Surface Push Broom  
GIS# 8ZD24 | 60" Steel Replacement Handle

## INDUSTRIAL

### Smooth Surface

- 24" polymer broom block for durability and hygiene.
- 1.13" x 60" long wood handle and 15" ergonomic grip with hanger tip.
- 3" long, soft, recycled PET, staple-set fibers.
- Super tough polymer brace won't rust or bend.
- Ergonomic grip allows for upright sweeping to minimize user fatigue.



GIS# 9WT18 | 24" Smooth Surface Push Broom

### Multi-Surface

- 24" polymer broom block for durability and hygiene.
- 1.13" x 60" long wood handle and 15" ergonomic grip with hanger tip.
- 4" long, combo of firm and flexible split tip recycled PET, staple-set fibers.
- Super tough polymer brace won't rust or bend.
- Ergonomic grip allows for upright sweeping to minimize user fatigue.



GIS# 8CNK5 | 24" Multi-Surface Push Broom

### Rough Surface

- 24" polymer broom block for durability and hygiene.
- 1.13" x 60" long wood handle and 15" ergonomic grip with hanger tip.
- 4" long, stiff, recycled PET, staple-set fibers.
- Super tough polymer brace won't rust or bend.
- Ergonomic grip allows for upright sweeping to minimize user fatigue.



GIS# 8CNK6 | 24" Rough Surface Push Broom

# LIBMAN

## COMMERCIAL



# Dust Pans

## LOBBY PAN SETS



TOP  
SELLER

- 11.75" wide dust pan. 36" tall when open.
- Broom stores inside pan and clips to handle.
- Handle grip has hanger hole.
- Locks in upright position for easy storage.
- Built-in tilt when open allows user to leave open.

GIS# 9DZE2 | Open Lid Lobby Dust Pan & Broom  
GIS# 9U482 | Closed Lid Lobby Dust Pan & Broom  
GIS# 9WT61 | Lobby Broom


## LARGE SCOOP



- 21.75" wide scoop. Oversized, 5.5" deep well.
- 33.5" telescopic steel handle.
- Hanger hole for storage.
- Durable hard resin design.
- Great for industrial/warehouse and construction clean-up.

GIS# 8EEZ5 | Outdoor/Shop Scoop

## 18" DUST PAN

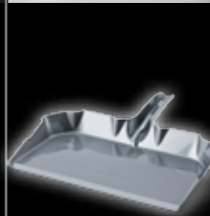

- Super durable polypropylene molded.
- Hanger hole for storage.
- Includes broom fiber cleaning teeth on the top edges of the dust pan.
- Withstands more than 530 lbs, reinforced to maintain shape, will not crack.

GIS# 46U287 | Industrial Grade Dust Pan

## DUST PAN/WHISK SET



- 10" dust pan
- 42 tufts of flexible, split-tip polymer fibers pick up fine particles.
- Ergonomic handle.
- Hanger hole for easy storage.
- Whisk snaps into dust pan.
- Ideal design for any maintenance kit.

GIS# 9TN79 | Dust Pan with Whisk Broom

# Angle Brooms

## WIDE ANGLE BROOM



TOP  
SELLER

- 15" wide broom with 55" total height.
- 1" steel handle with hanger hole.
- 6" long staple-set, flagged fibers.
- Solid, one-piece resin block.
- Firm but flexible, long-lasting fibers, made with recycled PET.
- Excellent for all multi-surface applications.

GIS# 9AUV9 | Wide Commercial Angle Broom

## ANGLE BROOM



- 13" wide broom with 55" total height.
- 1" steel handle with hanger hole.
- 5" long staple-set, flagged fibers.
- Solid, one-piece resin block.
- Firm but flexible, long-lasting fibers, made with recycled PET.
- Excellent for stiff wet sweep applications, including food service.

GIS# 8TN93 | Commercial Angle Broom

# Floor Squeegees & Scrubs

## RUBBER SQUEEGEE SETS



- 2" long curved vulcanized, natural rubber squeegee blade.
- Bolted metal frame with tapered handle connector.
- Hard rubber blade fastened with lock nuts.
- Excellent for removing mud or chemicals from outdoor or industrial applications.

GIS# 46U289 | 24" Curved Floor Squeegee Set  
GIS# 46U288 | 36" Curved Floor Squeegee Set

## FOAM SQUEEGEE SETS



- Black, closed-cell foam rubber blade.
- 18" includes 52" and 24" includes 58.5" long steel handle, connected with standard thread.
- Removes water from concrete, tile and brick.
- Rivet or screw set to hold squeegee onto the handle neck.

GIS# 46U291 | 18" Flex Blade Squeegee  
GIS# 46U290 | 24" Flex Blade Squeegee

## SOFT RUBBER SQUEEGEE SET



- 24" soft, synthetic rubber.
- Includes 59" long steel handle, connected with standard thread.
- Extra strong polymer support brace connects handle to squeegee.
- Hanger swivel tip handgrip.

GIS# 46U292 | Soft Rubber Floor Squeegee Set

## FLOOR SCRUBS



- 10.5" x 3.5" scrubbing surface.
- 1.5" long, recycled PET fibers, 10" wide scraper.
- Total height of 52"
- 10" x 6.5" dual-sided scrubbing surface.
- 1" thick steel handle with hanger hole.
- 3.5" long, recycled PET Fibers.

GIS# 9FRA9 | Floor Scrub & Handle  
GIS# 46U293 | Dual Surface Scrub Brush  
GIS# 8MHZ5 | Dual Surface Scrub Brush Head  
GIS# 8ZD24 | 60" Steel Replacement Handle

# Bowl Brushes/Plungers/Scrub Brushes

## TOILET BRUSH



- 103 tufts of extra durable, 1" long, recycled PET, staple-set fibers.
- 14.13" total length with full "U" shape fiber placement to reach deep under rim.
- Ergonomic rubbergrip handle with hanger hole.

GIS# 46U298 | Round Bowl Brush

## BRUSH & CADDY



- 103 tufts of 1" long, recycled PET, staple-set fibers.
- 15" total height.
- 5.5" x 5.5" caddy.
- Extra sturdy polypropylene molded base will not tip over.

GIS# 46U295 | Round Bowl Brush & Open Caddy

## BRUSH & CLOSED CADDY



- 103 tufts of 1" long, recycled PET, staple-set fibers.
- 14.5" total height.
- 4.5" x 5.5" caddy.
- Extra sturdy polypropylene molded base will not tip over.
- Air slits for faster drying

GIS# 46U296 | Round Bowl Brush & Closed Caddy

## PLUNGER & CADDY



- Extra durable thermoplastic rubber base.
- Extra long flange creates maximum suction performance.
- 23" total height.
- Oversized grip for easy handling and steel handle

GIS# 46U302 | Plunger & Caddy Set

## ANGLED BRUSH



- 100 tufts of 1" long, recycled PET, staple-set fibers.
- 16.25" total length with contoured grip handle.
- Full "U" shape fiber placement, 3.25" wide head.
- Angled handle to easily reach under rim.
- Ergonomic rubbergrip handle with hanger hole.

GIS# 46U297 | Angled Bowl & Urinal Brush

## POWER SCRUB



- 95 tufts of 1" long, recycled PET, staple-set fibers.
- 7" x 2.5" scrubbing surface with pointed end for corners.
- Comfortable contoured grip handle with easy-grip open end.
- Fibers are not flagged to withstand heavier debris and surfaces.

GIS# 46U299 | Power Scrub Brush

## GROUT BRUSH



- 33 tufts of extra durable, 7/8" recycled PET, staple-set fibers.
- .56" x 3.5" scrubbing surface.
- Angled head for getting into tight spaces.
- Narrow brush design, excellent for grout.
- Ergonomic rubbergrip handle with hanger hole.

GIS# 46U301 | Tile & Grout Brush

# Specialty Mops

## WONDER® MOP



- 16" long durable, cut-end strips
- 3/4" steel handle. Overall height of 64"
- Non-woven strips. Premium synthetic material. Absorbent and machine washable.
- Easy release mop head.
- Light weight mop, less than 3 pounds when wet.
- Excellent for all quick-clean needs.

GIS# 8E591 | Big Wonder® Mop  
GIS# 8E592 | Big Wonder® Mop Refill

## FREEDOM® SPRAY MOP



- 15" x 5" premium, thick absorbent pad provides a deep clean.
- Machine washable pad up to 100 times.
- Total mop length is 49".
- Mop head angled to reach tough corners.
- Removable and refillable fluid reservoir can be filled with any solution.
- Mop head swivels 360°.
- Excellent for quick cleaning on all hard surfaces.

GIS# 6APW2 | Freedom® Spray Mop  
GIS# 6APW3 | Freedom® Spray Mop Refill

For more information, contact your Grainger Representative or visit [Grainger.com](http://Grainger.com)®.

8SSP6106

AVAILABLE THROUGH

**GRAINGER**®

FOR THE ONES WHO GET IT DONE