



## PRODUCT FEATURES

- Flexible bracket options for swinging or sliding applications
- Fully sealed and conformal coated for weatherproof operations
- Includes universal threaded conduit fitting 1/2" female - 3/4" male
- Sealed 10 ft. [3.05m] jacketed, stranded conductor cable
- Automatic dual voltage - no field adjustment required
- All ferrous metal surfaces plated for durability
- MagnaCare Lifetime Replacement No Fault Warranty

## PRODUCT OPTIONS

- Flexible mounting options for
  - › Swinging gates
  - › Sliding gates
- SASM for shock absorption and rebound assistance for proper gate alignment

## SPECIFICATIONS

- UL 10C Listed
- CAN4-S104, CAN/ULC-S533 Listed

- ANSI/UL 294 Listed
- CSA-C22.2 No.205 Listed
- ANSI/BHMA 156.23, Grade 1; E08501-1000
- NFPA 101
- CSFM - California State Fire Marshal Approved
- MEA - City of New York Approved
- CE:EN 50091-1, EN 61000-6-2 Approved
- NEMA: 4X
- IEC: IP66

**Holding Force:**  
1200lbs [544kg]


**Dimensions:**  
8" L x 1-3/4" D x 3" H

**Electrical:**  
250mA at 12VDC  
125mA at 24VDC


**Operating Temperature:**  
-40 to +140F [-40 to +60C]  
Recommended for indoor or outdoor use

**Shipping Weight:**  
12lbs [5.44kg]

**Finishes:**  
US32D/630 - Satin Stainless Steel

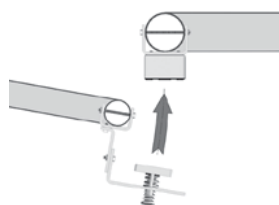

M62FG-SASM on Swinging Gate Using Flex-Mount Bracket Kit FMK-SW

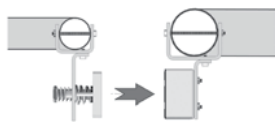

M62FG-SASM on Sliding Gate Using Flex-Mount Bracket Kit FMK-SL

# M62FG-SASM

## 1200lbs Holding Force Gate Magnalock®

### The Low Maintenance Magnalock Solution for Outdoor Gates

The M62FG-SASM is the only heavy duty Magnalock specifically designed to secure and protect gates. This weatherproof unit delivers 1200lbs of holding force and comes equipped with conduit fittings and a special shock absorbing strike mount (SASM). This unique design dramatically prolongs the life of the lock, the gate and other hardware by controlling excessive impact between the strike plate and the magnet.

The SASM is also available as a separate retrofit kit and is compatible with M32, M62 or M82 Magnalock strike plates for areas prone to excessive force closures or slamming.

## MODELS

PART # | Description

M62FG	M62 - Face Drilled, Gate Conduit
M62FG-SASM	M62 - Face Drilled, Gate Conduit w/ SASM Bracket
M62FGB	M62 - Face Drilled, Conduit, MBS
M62FGBD	M62 - Face Drilled, Conduit, MBS, DPS
M62FGD	M62 - Face Drilled, DPS, Gate Conduit
SASM	Shock Absorbing Strike Mount for M32, M62, M82



**SECURITRON®**  
**ASSA ABLOY**