



BRUTE[®]



THE TOUGHEST JUST GOT MORE PRODUCTIVE



SINCE 1968, BRUTE CONTAINERS have been trusted by professionals for their iconic durability and reliability. With every lift, drag and drop, they've outlasted – and outperformed every competitor in their industry thanks to their proprietary design and the highest quality materials. That's why our containers are chosen first to get the job done.

But we're raising the bar even higher with the new BRUTE. Innovative venting channels make removing liners up to 50% easier. Integrated cinches secure can liners, meaning knot-free liner changes. Contoured base handles improve grip, reduce strain and improve efficiency when emptying containers.

With these brand new innovations, we're proud to stamp BRUTE on every container guaranteeing its legendary performance. When you see our stamp, it means that your toughest job just got a whole lot easier.





50% EASIER TO LIFT LINERS

THE BRUTE IS DESIGNED WITH FOUR BUILT-IN VENTING CHANNELS that create airflow throughout the container. This air circulation eliminates the vacuum effect that occurs when lifting out liners in traditional containers. By reducing the pull force required to lift out liners by up to 50%, the BRUTE improves productivity and reduces the risk of injury.

800.347.9800



IMPROVED PRODUCTIVITY



VENTING CHANNELS

Make removing liners up to 50% easier, improving productivity and reducing the risk of injury.



BAG CINCHES

Secure liners allowing for knot-free liner changes. Tested to 20,000 cycles.



CONTOURED BASE HANDLES

Improve grip and ergonomics, reducing strain and improving efficiency when emptying containers.



SEAMLESS CONSTRUCTION

Helps make cleaning easier.



2 & 21 Compliant



BRUTE.



REDUCE TIME AND EFFORT NEEDED TO MANAGE REFUSE STREAMS

Overexertion is among the leading causes of workplace injuries according to the U.S. Department of Labor. The BRUTE delivers on improved productivity by managing and collecting refuse more efficiently and safely. BRUTE Containers reduce exertion through greater ergonomics when lifting, transporting and emptying refuse.



ICONIC DURABILITY



COMMERCIAL-GRADE CONSTRUCTION

Proprietary design constructed with the highest quality material plus a UV inhibitor ensures long life in even the most extreme commercial environments. Guaranteed to never fade, warp, crack, or crush.



RIM WITH RIB STRENGTHENED DESIGN

Increases strength and resists crushing.



ROUNDED HANDLES

Make lifting and moving easier, and are reinforced to resist tearing or damage from even the heaviest loads.



REINFORCED BASE

Specifically engineered to be dragged over rough surfaces, extending life and durability in even the toughest environments.



BRUTE.
Rubbermaid
Commercial Products

BRUTE

GUARANTEED TO NEVER FADE, WARP, CRACK OR CRUSH

For almost 50 years, professionals have trusted BRUTE to get the job done. Manufactured in Winchester, VA, BRUTE Containers feature a proprietary design constructed with the highest quality material plus a UV inhibitor to ensure long life in even the most extreme commercial environments. Every BRUTE must pass extreme durability performance standards ensuring our commitment to manufacture the toughest.

800.347.9800





SELF-DRAINING LIDS

SELF-DRAINING CHANNELS prevent water from pooling, reducing still water buildup.

SNAP-LOCK ensures a secure fit.


RIDGES ENABLE STACKING of BRUTE containers to provide a space-efficient storage solution.



DOMESTOP LIDS

SPRING ACTION DOOR allows easy trash disposal while keeping odors in and insects out.

SNAP-LOCK ensures a secure fit.

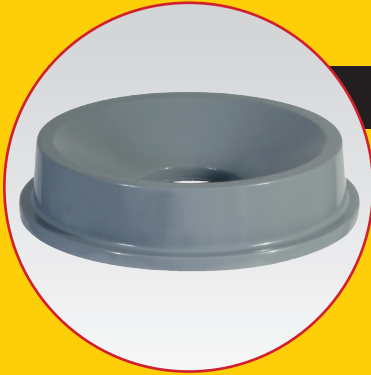

FUNNEL TOP LIDS

CUT-OUT TOP enables hands-free refuse disposal.

FUNNEL DESIGN conceals waste from public view.

MULTIPLE COLOR OFFERING

Recycling, sorting and organizational needs.



2 & 21 Compliant



DOLLY

FIVE RUGGED CASTERS - Help keep fully loaded BRUTEs stable, even on rough and uneven floors, and swivel smoothly for easy maneuvering.

STRUCTURAL FOAM CONSTRUCTION - Provides superior strength and durability, with a 250-pound load capacity.

NON-MARKING CASTERS - Help protect floors, keeping public areas looking their best.



TANDEM DOLLY

TWO TWIST LOCKS - Hold containers securely and unlock easily for unloading, allowing easy transport of two loaded 44-gallon BRUTEs for increased productivity.

HEAVY-DUTY 8" WHEELS AND 3" SWIVEL CASTERS - Maneuver easily across rough floors and around corners.

STRUCTURAL FOAM CONSTRUCTION - Provides superior strength and durability, with a 400-pound load capacity.



CADDY BAG

ELASTIC POCKETS - Knock out quick cleanups on-the-go with onboard storage for spray bottles, cleaning cloths, brushes, extra can liners, latex gloves, and other cleaning supplies.

HEAVY-DUTY VINYL - For long life and easy cleaning.

ADJUSTABLE STRAPS - Allow easy installation and removal on both 32 and 44-gallon BRUTEs.



RIM CADDY

MULTIPLE STORAGE COMPARTMENTS AND HOOKS - Provide storage for everything from wet floor signs to spray bottles to extra can liners and all the other cleaning supplies needed for on-the-go cleaning.

LINER RETENTION BANDS - Keep can liners securely in place and allow for quick liner changes for improved productivity.

SNAP-ON TABS - Hold caddy securely on a 44-gallon BRUTE, even when changing out full can liners.

BRUTE Containers

	DESCRIPTION	ITEM #	COLOR	HEIGHT	DIAMETER
10 GALLON	BRUTE 10 GALLON CONTAINER GRAY	FG261000GRAY	GRAY	17.13"	15.63"
	BRUTE 10 GALLON CONTAINER WHITE	FG261000WHT	WHITE	17.13"	15.63"
	BRUTE 10 GALLON CONTAINER RED	FG261000RED	RED	17.13"	15.63"
	BRUTE 10 GALLON CONTAINER YELLOW	FG261000YEL	YELLOW	17.13"	15.63"
	BRUTE 10 GALLON CONTAINER BLUE	1779699	BLUE	17.13"	15.63"
	BRUTE 10 GALLON CONTAINER DARK GREEN	FG261000DGRN	DARK GREEN	17.13"	15.63"
	BRUTE 10 GALLON CONTAINER BLACK	1926827	BLACK	17.13"	15.63"
20 GALLON	BRUTE 20 GALLON CONTAINER GRAY	FG262000GRAY	GRAY	22.91"	19.38"
	BRUTE 20 GALLON CONTAINER WHITE	FG262000WHT	WHITE	22.91"	19.38"
	BRUTE 20 GALLON CONTAINER RED	FG262000RED	RED	22.91"	19.38"
	BRUTE 20 GALLON CONTAINER YELLOW	FG262000YEL	YELLOW	22.91"	19.38"
	BRUTE 20 GALLON CONTAINER BLUE	FG262000BLUE	BLUE	22.91"	19.38"
	BRUTE 20 GALLON CONTAINER DARK GREEN	FG262000DGRN	DARK GREEN	22.91"	19.38"
	BRUTE 20 GALLON CONTAINER BLACK	1779734	BLACK	22.91"	19.38"
	BRUTE 20 GALLON RECYCLING CONTAINER BLUE	FG262073BLUE	BLUE	22.91"	19.38"
	BRUTE 20 GALLON RECYCLING CONTAINER DARK GREEN	1926828	DARK GREEN	22.91"	19.38"
32 GALLON	BRUTE 32 GALLON CONTAINER GRAY	FG263200GRAY	GRAY	27.77"	21.92"
	BRUTE 32 GALLON CONTAINER WHITE	FG263200WHT	WHITE	27.77"	21.92"
	BRUTE 32 GALLON CONTAINER RED	FG263200RED	RED	27.77"	21.92"
	BRUTE 32 GALLON CONTAINER YELLOW	FG263200YEL	YELLOW	27.77"	21.92"
	BRUTE 32 GALLON CONTAINER BLUE	FG263200BLUE	BLUE	27.77"	21.92"
	BRUTE 32 GALLON CONTAINER DARK GREEN	FG263200DGRN	DARK GREEN	27.77"	21.92"
	BRUTE 32 GALLON CONTAINER BLACK	1867531	BLACK	27.77"	21.92"
	BRUTE 32 GALLON RECYCLING CONTAINER BLUE	FG263273BLUE	BLUE	27.77"	21.92"
	BRUTE 32 GALLON RECYCLING CONTAINER DARK GREEN	1788472	DARK GREEN	27.77"	21.92"
44 GALLON	BRUTE 44 GALLON CONTAINER GRAY	FG264360GRAY	GRAY	31.50"	24.00"
	BRUTE 44 GALLON CONTAINER WHITE	1779740	WHITE	31.50"	24.00"
	BRUTE 44 GALLON CONTAINER RED	FG264360RED	RED	31.50"	24.00"
	BRUTE 44 GALLON CONTAINER YELLOW	FG264360YEL	YELLOW	31.50"	24.00"
	BRUTE 44 GALLON CONTAINER BLUE	FG264360BLUE	BLUE	31.50"	24.00"
	BRUTE 44 GALLON CONTAINER DARK GREEN	1779741	DARK GREEN	31.50"	24.00"
	BRUTE 44 GALLON CONTAINER BLACK	FG264360BLA	BLACK	31.50"	24.00"
	BRUTE 44 GALLON RECYCLING CONTAINER BLUE	FG264307BLUE	BLUE	31.50"	24.00"
	BRUTE 44 GALLON RECYCLING CONTAINER DARK GREEN	1926829	DARK GREEN	31.50"	24.00"
55 GALLON	BRUTE 55 GALLON CONTAINER GRAY	FG265500GRAY	GRAY	33.19"	26.38"
	BRUTE 55 GALLON CONTAINER WHITE	FG265500WHT	WHITE	33.19"	26.38"
	BRUTE 55 GALLON CONTAINER RED	FG265500RED	RED	33.19"	26.38"
	BRUTE 55 GALLON CONTAINER YELLOW	FG265500YEL	YELLOW	33.19"	26.38"
	BRUTE 55 GALLON CONTAINER BLUE	1779732	BLUE	33.19"	26.38"
	BRUTE 55 GALLON CONTAINER DARK GREEN	FG265500DGRN	DARK GREEN	33.19"	26.38"
	BRUTE 55 GALLON CONTAINER BLACK	1779739	BLACK	33.19"	26.38"

10 & 55 GALLON CONTAINERS FEATURE STRAIGHT WALL DESIGN



BRUTE Lids and Accessories

	DESCRIPTION	ITEM #	COLOR	LENGTH	WIDTH	HEIGHT	DIAMETER
10 GALLON	BRUTE 10 GALLON LID GRAY	FG260900GRAY	GRAY	—	—	1.25"	17.13"
	BRUTE 10 GALLON LID WHITE	FG260900WHT	WHITE	—	—	1.25"	17.13"
	BRUTE 10 GALLON LID RED	FG260900RED	RED	—	—	1.25"	17.13"
	BRUTE 10 GALLON LID YELLOW	FG260900YEL	YELLOW	—	—	1.25"	17.13"
	BRUTE 10 GALLON LID BLUE	1779700	BLUE	—	—	1.25"	17.13"
	BRUTE 10 GALLON LID DARK GREEN	FG260900DGRN	DARK GREEN	—	—	1.25"	17.13"
	BRUTE 10 GALLON LID BLACK	1926826	BLACK	—	—	1.25"	17.13"
20 GALLON	BRUTE 20 GALLON LID GRAY	FG261960GRAY	GRAY	—	—	1.80"	19.88"
	BRUTE 20 GALLON LID WHITE	FG261960WHT	WHITE	—	—	1.80"	19.88"
	BRUTE 20 GALLON LID RED	FG261960RED	RED	—	—	1.80"	19.88"
	BRUTE 20 GALLON LID YELLOW	FG261960YEL	YELLOW	—	—	1.80"	19.88"
	BRUTE 20 GALLON LID BLUE	1779731	BLUE	—	—	1.80"	19.88"
	BRUTE 20 GALLON LID DARK GREEN	FG261960DGRN	DARK GREEN	—	—	1.80"	19.88"
	BRUTE 20 GALLON LID BLACK	FG261960BLA	BLACK	—	—	1.80"	19.88"
32 GALLON	BRUTE 32 GALLON LID GRAY	FG263100GRAY	GRAY	—	—	1.85"	22.41"
	BRUTE 32 GALLON LID WHITE	FG263100WHT	WHITE	—	—	1.85"	22.41"
	BRUTE 32 GALLON LID RED	FG263100RED	RED	—	—	1.85"	22.41"
	BRUTE 32 GALLON LID YELLOW	FG263100YEL	YELLOW	—	—	1.85"	22.41"
	BRUTE 32 GALLON LID BLUE	FG263100BLUE	BLUE	—	—	1.85"	22.41"
	BRUTE 32 GALLON LID DARK GREEN	FG263100DGRN	DARK GREEN	—	—	1.85"	22.41"
	BRUTE 32 GALLON LID BLACK	1867532	BLACK	—	—	1.85"	22.41"
	BRUTE 32 GALLON FUNNEL TOP GRAY	FG354300GRAY	GRAY	—	—	5.00"	22.38"
	BRUTE 32 GALLON DOME TOP GRAY	FG263788GRAY	GRAY	—	—	12.25"	22.69"
	BRUTE 32 GALLON DOME TOP RED	FG263788RED	RED	—	—	12.25"	22.69"
	BRUTE 32 GALLON DOME TOP DARK GREEN	1829397	DARK GREEN	—	—	12.25"	22.69"
	BRUTE 32 GALLON DOME TOP BLUE	1829398	BLUE	—	—	12.25"	22.69"
	BRUTE 32 GALLON DOME TOP YELLOW	1829399	YELLOW	—	—	12.25"	22.69"
44 GALLON	BRUTE 44 GALLON LID GRAY	FG264560GRAY	GRAY	—	—	2.00"	24.50"
	BRUTE 44 GALLON LID WHITE	FG264560WHT	WHITE	—	—	2.00"	24.50"
	BRUTE 44 GALLON LID RED	FG264560RED	RED	—	—	2.00"	24.50"
	BRUTE 44 GALLON LID YELLOW	FG264560YEL	YELLOW	—	—	2.00"	24.50"
	BRUTE 44 GALLON LID BLUE	1779636	BLUE	—	—	2.00"	24.50"
	BRUTE 44 GALLON LID DARK GREEN	FG264560DGRN	DARK GREEN	—	—	2.00"	24.50"
	BRUTE 44 GALLON LID BLACK	FG264560BLA	BLACK	—	—	2.00"	24.50"
	BRUTE 44 GALLON DOME TOP GRAY	FG264788GRAY	GRAY	—	—	12.63"	24.81"
	BRUTE 44 GALLON DOME TOP RED	FG264788RED	RED	—	—	12.63"	24.81"
	BRUTE 44 GALLON DOME TOP DARK GREEN	1834838	DARK GREEN	—	—	12.63"	24.81"
	BRUTE 44 GALLON DOME TOP YELLOW	1834839	YELLOW	—	—	12.63"	24.81"
	BRUTE 44 GALLON DOME TOP BLUE	1834840	BLUE	—	—	12.63"	24.81"
55 GALLON	BRUTE 55 GALLON LID GRAY	FG265400GRAY	GRAY	—	—	2.09"	29.06"
	BRUTE 55 GALLON LID WHITE	FG265400WHT	WHITE	—	—	2.09"	29.06"
	BRUTE 55 GALLON LID RED	FG265400RED	RED	—	—	2.09"	29.06"
	BRUTE 55 GALLON LID YELLOW	FG265400YEL	YELLOW	—	—	2.09"	29.06"
	BRUTE 55 GALLON LID BLUE	1779733	BLUE	—	—	2.09"	29.06"
	BRUTE 55 GALLON LID DARK GREEN	FG265400DGRN	DARK GREEN	—	—	2.09"	29.06"
	BRUTE 55 GALLON LID BLACK	1779738	BLACK	—	—	2.09"	29.06"
	BRUTE 55 GALLON DOME TOP GRAY	FG265788GRAY	GRAY	—	—	14.50"	27.25"
	BRUTE 55 GALLON DOME TOP RED	FG265788RED	RED	—	—	14.50"	27.25"
ACCESSORIES	BRUTE DOLLY	FG264000BLA	BLACK	—	—	6.63"	18.25"
	BRUTE QUIET DOLLY	FG264043BLA	BLACK	—	—	6.63"	18.25"
	BRUTE TANDEM DOLLY	FG264600BLA	BLACK	45.00	20.25	8.00"	—
	BRUTE CADDY BAG	FG264200YEL	YELLOW	—	—	20.50"	20.00"
	BRUTE RIM CADDY	FG9W8700YEL	YELLOW	32.5	26.5	6.75"	—

10 & 55 GALLON LIDS FEATURE TRADITIONAL DESIGN

800.347.9800





To see our complete range of refuse solutions visit our online catalog at rubbermaidcommercial.com

RCP-327
©2014 Rubbermaid Commercial Products LLC
8900 Northpointe Executive Drive, Huntersville, NC 28078

