



PODIUM WITH CASTERS

375lbs TYPE IAA

Load Capacity

Duty Rating




WORK FACING ANY DIRECTION



Factory installed casters for added mobility



Extra-large platform for all-day comfort

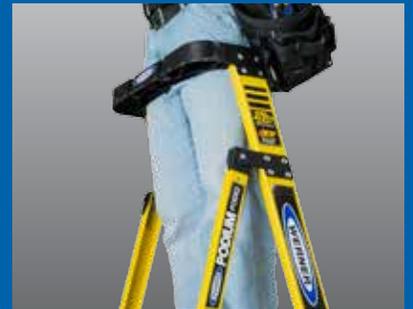

36" high extended guard rail



LOCKTOP™ secures tools and accessories



PODIUM WITH CASTERS

ADDED MOBILITY FOR WORKING AT FIXED HEIGHTS



The NEW PD7300-4C Podium Ladder series with factory installed casters for added mobility is ideal for working at fixed heights and is easier to maneuver than scaffolds or lifts.

- The extra-large platform with toe guard feels like you are standing on the ground.
- This ladder features full aluminum bracing and a full set of rear horizontals.
- LOCKTOP™ extended guardrail provides an extra point of contact and conveniently organizes tools and accessories.
- The durable caster assembly with stainless steel spring, steel stem and ball bearing swivel eliminates the need for a separate brake.
- The 4 soft rubber casters allow for easy 360 degree mobility and designed to roll over thresholds.

SPECIFICATIONS

★★★★★ **375** lbs. LOAD CAPACITY Includes User and Materials Type IAA Duty Rating

Model No.	Platform Height	Maximum Reach	Comparable Stepladder Height	Approx. Weight
PD7303-4C	3'	9'	5'	21 lbs.
PD7304-4C	4'	10'	6'	26.5 lbs.
PD7306-4C	6'	12'	8'	38.5 lbs.
PD7308-4C	8'	14'	10'	45.5 lbs.

LOCK-IN ACCESSORIES



AC27-P Lock-In Paint Cup



AC50-JB-3 Lock-In Job Bucket



AC52-UB Lock-In Utility Bucket



AC54-JC Lock-In Job Caddy

wernerpodium.com

WERNER CO. CORPORATE HEADQUARTERS: 93 Werner Rd., Greenville, PA 16125-9499
 TEL: 888-523-3370 FAX: 724-588-0315 www.wernerladder.com