



QUICK-RELEASE SPRING

Prevents roller from slipping, yet allows easy, "hands free" removal



MILLIONS OF PAINTERS CAN'T BE WRONG!

WOOSTER®

SHERLOCK®

There are many reasons why Sherlock is the world's best-selling professional frame. The quick-release spring prevents roller slippage, yet allows clean, one-rap removal. Internal bearings keep the durable, fiberglass-reinforced nylon cage spinning smoothly. All Sherlock frames also have a 90-degree, chrome-plated, 5/16-inch shank for control. And the comfortable, full-size grip works perfectly with extension poles, including Sherlock GT®.



EXTRA-STRONG CAGE

Professional durability

SMOOTH ROLLING

Bearings keep spinning smoothly



THREADS & GT™

Frame attaches easily to extension poles

Cat. No.	UPC 0-71497-	Size	Overall Length	Case Qty.	Cubic Ft. Per Case	Pounds Per Case
R017	13609-1	4"	14½"	6	.376	3.80
	12534-7	7	15	6	.631	5.02
	69079-1	9	15	6	.631	5.56
	16779-8	14	15	6	.802	8.50
BR017	11870-7	9½"	15"	12	1.197	11.12

Every roller performs better when it's attached to an American-made Wooster frame.

15 Degree

Fits inside a 5-gallon bucket with the lid closed—saves painters startup and cleanup time. Chrome-plated 5/16" shank has a 15-degree angle for balanced center of gravity. Sturdy 5-wire cage with nylon endcaps keeps the roller cover round. Full-size polypropylene threaded grip, Sherlock GT® compatible.



Magikage® Ninety

Chrome-plated 5/16" shank with a popular 90-degree angle. Sturdy 5-wire cage, nylon endcaps. Comfortable polypropylene threaded grip, Sherlock GT compatible.




Ex Magikage

The Wooster roller frame with the most built-in reach, its chrome-plated 5/16" shank measures 18" long. Sturdy 5-wire cage with nylon endcaps. Comfortable polypropylene threaded grip, Sherlock GT compatible.



Deluxe Magikage

It's the perfect price-point professional frame, with performance features and cost-saving components in one. Sturdy 5-wire cage, polypropylene endcaps. Chrome-plated 1/4" shank. Comfortable polypropylene threaded grip, Sherlock GT compatible.

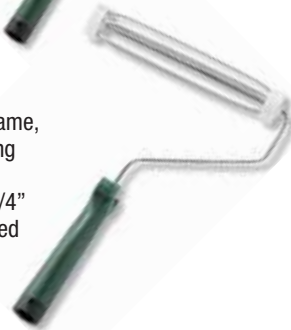

501™ Frame

Polypropylene handle is wrapped in soft, blue Sherogrip® elastomeric material to add comfort while painting. Smooth design with thumb groove improves grip and control. Threaded for extension pole use. Sturdy 5-wire cage keeps the roller cover round. Galvanized 1/4" shank, blue polypropylene endcaps.



Utility

Good-quality paint roller frame with a 5-wire cage to keep the roller cover round. Galvanized 1/4" shank, polypropylene endcaps. Polypropylene grip, threaded for extension pole use.



Magikage Trafficage

Perfect for lines, edging, and trim work. Sturdy 5-wire cage, built like standard 9" frames, keeps the roller cover round. Galvanized 1/4" shank, polypropylene endcaps and threaded grip.



Description	Cat. No.	UPC 0-71497-	Size	Overall Length	Case Qty.	Cubic Ft. Per Case	Pounds Per Case
15 Degree	R015	66289-7	9"	14"	12	.802	10.77
Magikage Ninety	R016	66277-4	7"	15"	12	.802	9.93
		66279-8	9"	15"	12	.802	11.26
		KR016	17034-7	9½"	15"	6	.802
Ex Magikage	R027	66269-9	9"	18"	12	1.330	11.54
Deluxe Magikage	R032	63209-8	9"	14"	12	.708	8.46
501 Frame	R501	13432-5	9"	14"	12	.676	8.25
Utility	R030	60099-8	9"	14"	12	.676	7.43
Magikage Trafficage	R022	66294-1	4"	11"	12	.376	4.44