




Series	30	Sleeve Material	Steel
Shut Off	Double	Coupler Body Size	1/4"
Seal Type	Captive Valve	Coupler Flow Rate	3.0 gpm
Valve Design	Poppet	Locking Mechanism	Screw Together
Seal Material	Buna	Coupler Thread Size	1/4"-18
Max. Pressure	10,000 psi	Coupler Body Material	Steel

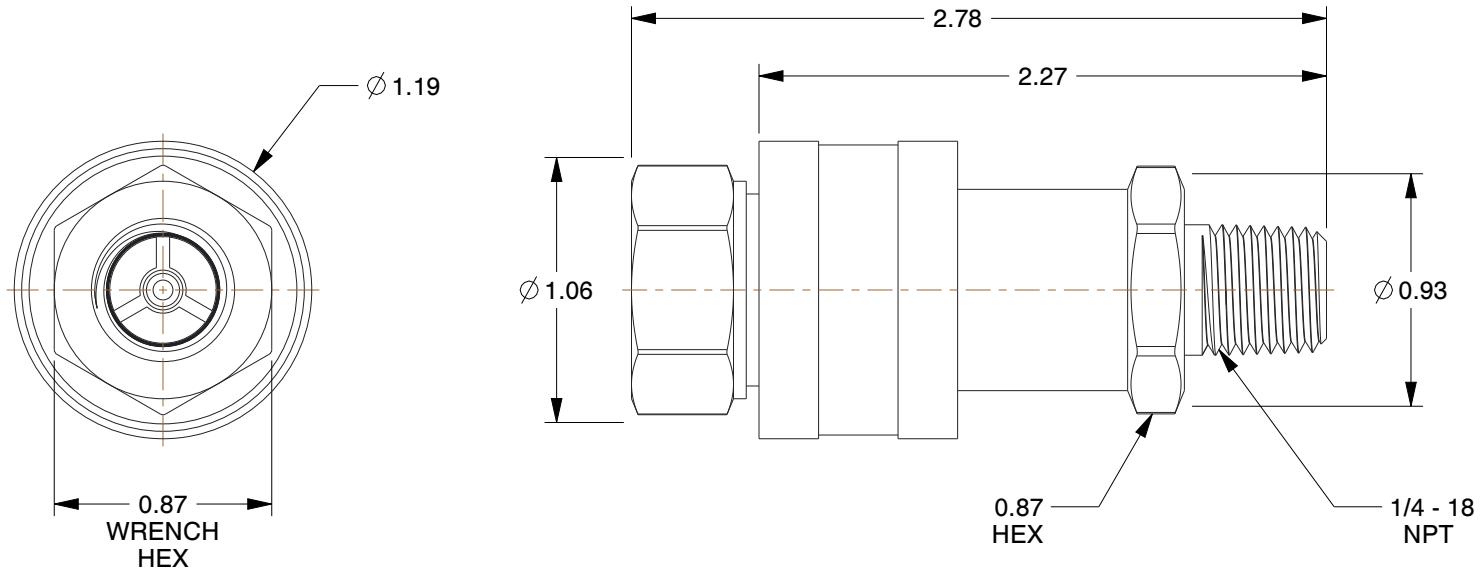

NOTES:

- ITEM: Hydraulic Coupler Set
- COUPLER INTERCHANGE TYPE: S30
- COUPLER CONNECTION TYPE: FNPT
- FOR USE WITH: Mfr. No. P-142, RSM-50
- PARKER INTERCHANGE: 3010-2 & 3050-2
- OPERATING TEMP. RANGE: -40° to 250°F
- COUPLER FINISH: Trivalent Chromium Zinc
- QUICK COUPLER TYPE: Hydraulic Coupler Set
- HANSEN INTERCHANGE: WA 56517 00 & WA 56514 00

COMPONENT	Hydraulic Quick Couplers
------------------	--------------------------



100 Grainger Parkway, Lake Forest, Illinois 60045-5201
 1-(800) GRAINGER, 1-(800) 472-4643, (847) 535-1000
 www.grainger.com

This file and any associated information and specifications are provided for reference and evaluation purposes only, and is subject to change without notice. Grainger makes no representations, warranties or guarantees as to the appropriateness, accuracy, completeness, or suitability for any purpose, of the file, information or specifications. You are solely responsible for the use of the file, information or specifications.

This drawing is the property of GRAINGER. It contains confidential, proprietary information that is GRAINGER property. Do not disclose to or duplicate for others except as authorized by GRAINGER.

SCALE 1.30

3KD28
 Coupler Set, 1/4-18, 1/4 In. Body, Steel

UNIT	INCH
SHEET	1 of 1